


KPDF-AP-A

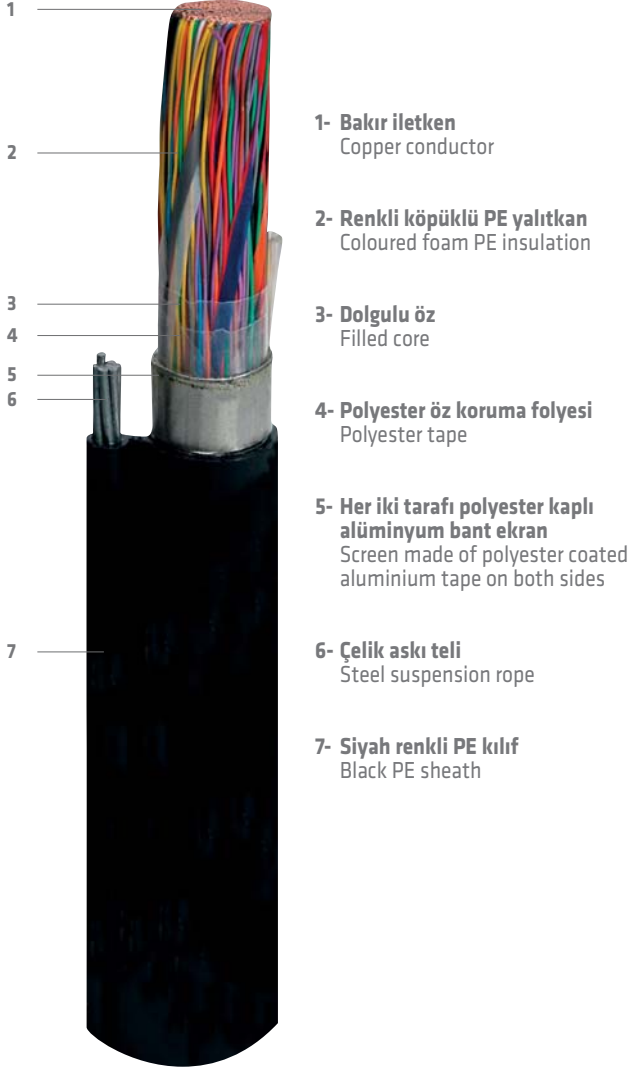

- 1- Bakır iletken
Copper conductor
- 2- Renkli köpüklü PE yalıtkan
Coloured foam PE insulation
- 3- Dolgu öz
Filled core
- 4- Polyester öz koruma folyesi
Polyester tape
- 5- Her iki tarafı polyester kaplı alüminyum bant ekran
Screen made of polyester coated aluminium tape on both sides
- 6- Çelik askı teli
Steel suspension rope
- 7- Siyah renkli PE kılıf
Black PE sheath

Yapı / Construction

Tavlı elektrolitik bakır iletkenli, 0,4-0,5-0,6 ve 0,9 mm iletken çaplı, köpüklü polietilen yalıtkanlı, kablo özütü dörtlü kablo demetlerinden oluşan, özel jel dolgulu, öz üzeri polyester folye sarılı, alüminyum bant ekranlı, polietilen dış kılıflı, askı halatlı havai hat telefon kablolarıdır.

Annealed electrolytic copper conductor, 0,4-0,5-0,6 and 0,9 mm conductor diameter, foam-skin polyethylene insulated, quads are stranded to form sub-units which are also stranded to make the cable core, with a special gel, wrapped with polyester foil, aluminum tape screened, with polyethylene outer sheathed, to contains with galvanized steel suspension rope overhead telephone cables.

Teknik Bilgiler / Technical Data

Sabit koşullardaki sıcaklığı : -30 °C, +70 °C
Hareketli koşullardaki sıcaklığı : -5 °C, +50 °C

Temp. for stationary condition : -30 °C, +70 °C
Temp. for moving condition : -5 °C, +50 °C

Kullanıldığı Yerler / Applications

Telefon santrallerinin irtibat ve dağıtım şebekelerinde, abone dağıtım şebekelerinde, ayrıca sinyal ve kumanda devrelerinde kullanılırlar. Beton kanal, PVC veya çimento boru içine çekilebilir veya doğrudan toprağa gömülebilirler.

This cable is used in the connection and distribution networks of the telephone switchboards, subscribers distribution networks and signal and control circuits. They are installed either in trenches, PVC or concrete conduits or buried directly in the soil.



Minimum İşletme Sıcaklığı
Minimum Operating Temperature



Maksimum İşletme Sıcaklığı
Maximum Operating Temperature



Kurşunsuz
Lead Free



Rijit
Rigid



Bükülme Yarıçapı
Bending Radius
Min 15xD

Kullanıldığı Yerler / Applications



Açıkta
In Free Air



Havai Hat
Aerial

Teknik Özellikler / Technical Features

KPDF-AP-A

Nominal İletken Çapı	Kapasite (En Çok)		20 °C'deki İletken Direnci (En Çok)	20 °C'deki Yalıtım Direnci (En Az)	Test Gerilimi (1dk, Vdc)	Çalışma Gerilimi
Nominal Conductor Diameter	Maximum Capacitance		Maximum Conductor Resistance at 20 °C	Min. Insulation Resistance at 20 °C	Test Voltage (1 min, Vdc)	Operating Voltage
mm	(nF/Km)		Ω/km	M.Ω.km	V	V
	Ort.-Avg	Bir.-Ind.				

0,4	50	56	139,4	>10000	1400	300
0,5	50	56	89,4	>10000	1400	300
0,6	45	51	62,1	>15000	2000	300
0,9	45	51	27,6	>15000	3000	300

Çift Sayısı / İletken Çapı	Kablo Dış Çapı (Yaklaşık)	Net Ağırlık (Yaklaşık)	Dış Kılıf Rengi	Ürün Numarası
Number of Pairs / Conductor Diameter	Overall Diameter of Cable (Apprx.)	Net Weight (Apprx.)	Outer Sheath Colour	Product Number

10x2x0,4 mm	8,55x17,2	142	Siyah - Black	60006786
20x2x0,4 mm	9,93x18,6	178	Siyah - Black	60006787
30x2x0,4 mm	10,48x19,2	209	Siyah - Black	60006789
50x2x0,4 mm	12,87x22,2	305	Siyah - Black	60006790
100x2x0,4 mm	16,02x26	496	Siyah - Black	60006791
150x2x0,4 mm	18,48x29,1	676	Siyah - Black	60006792
200x2x0,4 mm	20,59x32,4	895	Siyah - Black	60006793

4x2x0,5 mm	7,61x16,2	123	Siyah - Black	60006794
6x2x0,5 mm	8,32x17	137	Siyah - Black	60006795
10x2x0,5 mm	9,44x18,7	184	Siyah - Black	60006796
20x2x0,5 mm	11,13x20,5	236	Siyah - Black	60006797
30x2x0,5 mm	12,84x22,2	295	Siyah - Black	60006798
50x2x0,5 mm	15,45x25,4	427	Siyah - Black	60006799
100x2x0,5 mm	19,72x30,3	711	Siyah - Black	60006800
150x2x0,5 mm	22,87x34,7	1.024	Siyah - Black	60006801
200x2x0,5 mm	26,4x40,2	1.296	Siyah - Black	60006802

10x2x0,6 mm	11,1x20,4	222	Siyah - Black	60006803
20x2x0,6 mm	13,51x22,9	298	Siyah - Black	60006804
30x2x0,6 mm	15,35x25,3	402	Siyah - Black	60006805
50x2x0,6 mm	17,89x28,5	576	Siyah - Black	60006806
100x2x0,6 mm	24,76x36,6	1.047	Siyah - Black	60006807
150x2x0,6 mm	29,58x43,4	1.441	Siyah - Black	60006808
200x2x0,6 mm	33,43x48,4	1.892	Siyah - Black	60006809

10x2x0,9 mm	14,34x23,7	332	Siyah - Black	60006810
20x2x0,9 mm	18,43x28,4	518	Siyah - Black	60006811
30x2x0,9 mm	21,37x32	721	Siyah - Black	60006812
50x2x0,9 mm	25,81x37,7	1.123	Siyah - Black	60006813