

2.4. Patchpanels



- Cat6 compliant performance
- 90° termination blocks for easy termination
- Compatible with 110 & Krone Punch Tools
- Built in cable management
- Lasermark labels available on request

UC C400 PP TR U BK 48 1U

48port Cat6 UTP 90° Punchdown Panel,
Rear Management in Black




Specification

Item	Description
Panel	SPCC, 1.5mm thickness
RJ45 jack contact material and finish	Phosphor Bronze
Contact area	Min 3 mm 50 micro-inch Gold plated over Nickel colour
IDC terminal and finish	Phosphor Bronze with min, 50 micro-inch Tin plated
Wire size compatibility	23-26 AWG solid wire
Dimensions	482 x 44 x 143 mm

Performance

Item	Description
IDC cap colour code	supports both wiring schemes TIA 568A & 568B
Insertion force	20N max
Retention strength	7.7kg between jack and plug
Operating temperature	-10°C to 60°C
Durability	Jack 750 cycles

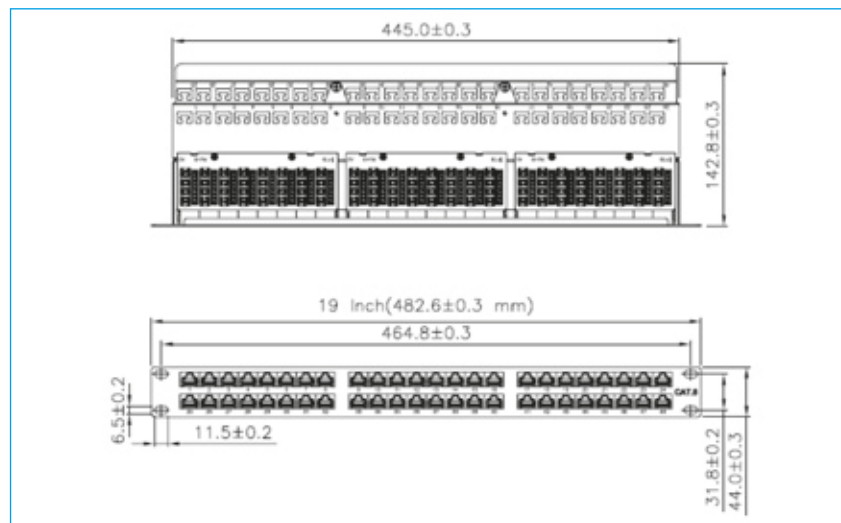

Technical data

Product code	Product name	Description	Weight	Items per packaging unit
			g	
YPPBP00111	UC C400 PP TR U BK 24 1U	1U 24port Cat6 UTP 90° Punchdown Panel with Rear Management in Black	975	1 or 20