

## 7.2. Patch Panel

## UC CAOF PM SO ME 1U


1U 19" Distribution Sliding-type Panel, Empty



- Available in FC, LC, MT-RJ, SC or ST
- Available in OS2, OM1, OM2, OM3 and OM4
- Plug & Play Installation
- Maximum Packing Density

## Construction

<b>Dust Cover</b>	Aluminum, T = 2.0mm
<b>Matrix</b>	Aluminum, T = 2.0mm
<b>Adapter Plate</b>	Aluminum, T = 1.5mm
<b>Splice Tray</b>	ABS
<b>Panel</b>	Aluminum
<b>Lock</b>	Stainless panel screw
<b>Adapter</b>	Duplex LC, SC
<b>Dimension</b>	H x W x D = 1U x 482mm x 310mm
<b>Weight</b>	Appr 2.2kg (empty panel)
<b>Surface Finish</b>	Power coating

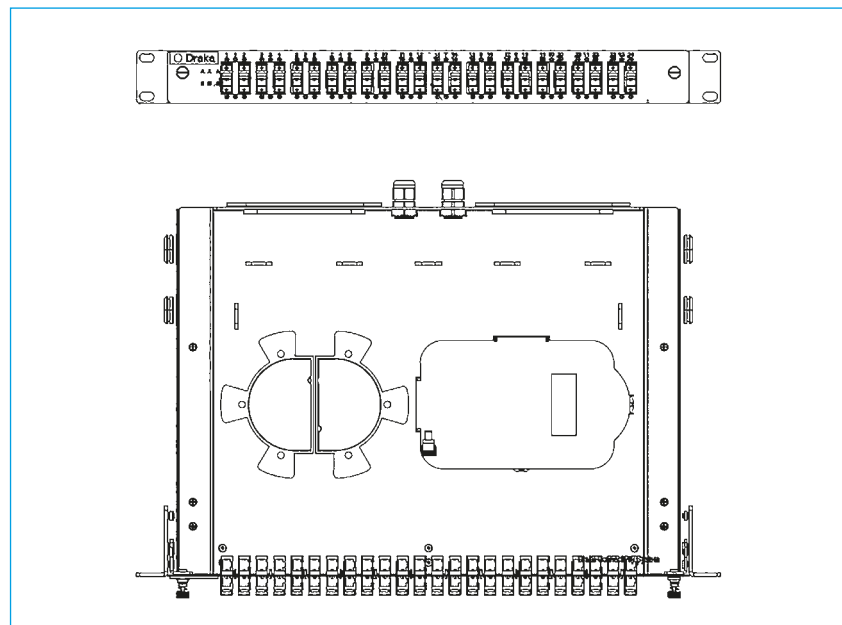

## Technical data

Item No.	SAP Description	Material Description	Weight	Items per packaging unit
			g	
<b>YPMBP01507</b>	UC CAOF PM SO ME 1U	1U 19" Distribution Sliding-type Panel, Empty	2500	1

## Related Products

<b>YAPBP01457</b>	UC CAOF AP SD 12 1U	1U front 12 Duplex SC plate w/o adapter	150g	1
<b>YAPBP01458</b>	UC CAOF AP ST 24 1U	1U front 24 ST plate w/o adapter	150g	1
<b>YAPBP01459</b>	UC CAOF AP FC 24 1U	1U front 24 FC plate w/o adapter	150g	1
<b>YAPBP01460</b>	UC CAOF AP LD 24 1U	1U front 24 LC Duplex plate w/o adapter	300g	1
<b>YAPBP01461</b>	UC CAOF AP MT 24 1U	1U front 24 MTRJ (Duplex) plate w/o adapter	300g	1
<b>YAPBP01462</b>	UC CAOF AP MP 12 1U	1U front 12 MTP plate w/o adapter	300g	1