


## 7.3. Patch Leads

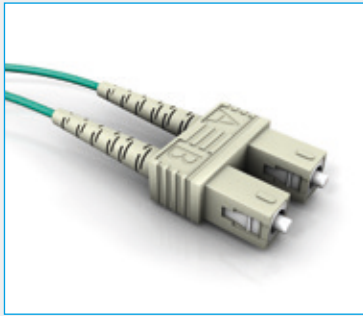

#### OM4 Patchcords compatible with UC<sup>CONNECT</sup> system

- Available with LC / SC & ST Connectors
- BendBright OM4 fibre at core, in accordance with ITU-T
- Robust and flexible

# UC COM4 PC

## Duplex 50/125 OM4 Patchcord

### Specification

<b>Fibre specifications</b>	BendBright OM4 Fibre As per Draka Datasheet - C32
<b>Fibre coating</b>	900 µm Tight coating
<b>Colour</b>	Turquoise
<b>Operating temperature</b>	- 40 °C to + 70 °C
<b>Bending radius</b>	Minimum 20 mm
<b>Diameter</b>	2.8 x 5.7 mm

### Performance

<b>Mating durability:</b>	500 cycles
<b>Applications</b>	10Base-T, 100Base-T, 1000Base-T, 10GBase-T (Class Ea)
<b>Fibre Specification</b>	As per Draka Datasheet C32
<b>Fibre bending loss</b>	R=7.5 mm 850/1300 nm ≤ 0.2 dB / ≤ 0.5 dB
<b>Fibre bending loss</b>	R=15 mm 850/1300 nm ≤ 0.1 dB / ≤ 0.3 dB

### Technical data

Item No.	SAP Description	Material Description	Measures	Weight	Items per packaging unit
			M	g	
<a href="#">YPCBP00197</a>	UC COM4 PC LC R AQ 00100	LC - LC Duplex 50/125 OM4 Patchcord 1m	1	30	1 or 12
<a href="#">YPCBP00200</a>	UC COM4 PC LC SC AQ 00100	LC - SC Duplex 50/125 OM4 Patchcord 1m	1	32	1 or 12
<a href="#">YPCBP00203</a>	UC COM4 PC LC ST AQ 00100	LC - ST Duplex 50/125 OM4 Patchcord 1m	1	35	1 or 12
<a href="#">YPCBP00198</a>	UC COM4 PC LC R AQ 00200	LC - LC Duplex 50/125 OM4 Patchcord 2m	1	30	1 or 12
<a href="#">YPCBP00201</a>	UC COM4 PC LC SC AQ 00200	LC - SC Duplex 50/125 OM4 Patchcord 2m	1	32	1 or 12
<a href="#">YPCBP00204</a>	UC COM4 PC LC ST AQ 00200	LC - ST Duplex 50/125 OM4 Patchcord 2m	1	35	1 or 12
<a href="#">YPCBP00199</a>	UC COM4 PC LC R AQ 00300	LC - LC Duplex 50/125 OM4 Patchcord 3m	1	30	1 or 12
<a href="#">YPCBP00202</a>	UC COM4 PC LC SC AQ 00300	LC - SC Duplex 50/125 OM4 Patchcord 3m	1	32	1 or 12
<a href="#">YPCBP00205</a>	UC COM4 PC LC ST AQ 00300	LC - ST Duplex 50/125 OM4 Patchcord 3m	1	35	1 or 12

### Related Products

<a href="#">YPPBP00212</a>	UC COMF PP LD SO BK 24 1U	1U 24 Port LC Duplex Multimode Patch Panel Black	n/a	n/a	n/a
<a href="#">YPPBP00213</a>	UC COMF PP LD SO BK 12 1U	1U 12 Port LC Duplex Multimode Patch Panel Black	n/a	n/a	n/a
<a href="#">YPPBP00214</a>	UC COMF PP SD SO BK 24 1U	1U 24 Port SC Duplex Multimode Panel Black	n/a	n/a	n/a
<a href="#">YPPBP00215</a>	UC COMF PP SD SO BK 12 1U	1U 12 Port SC Duplex Multimode Panel Black	n/a	n/a	n/a
<a href="#">YPPBP00216</a>	UC COMF PP ST SO BK 24 1U	1U 24 Port ST Simplex Multimode Panel Black	n/a	n/a	n/a
<a href="#">YPPBP00217</a>	UC COMF PP ST SO BK 12 1U	1U 12 Port ST Simplex Multimode Panel Black	n/a	n/a	n/a
<a href="#">YPPBP00218</a>	UC COSF PP LD SO BK 24 1U	1U 24 Port LC Duplex Single mode Panel Black	n/a	n/a	n/a
<a href="#">YPTBP00194</a>	UCCOM4 PT LC R AQ 00100	LC OM4 50/125 Pigtail 1m	n/a	n/a	n/a
<a href="#">YPTBP00195</a>	UCCOM4 PT SC R AQ 00100	SC OM4 50/125 Pigtail 1m	n/a	n/a	n/a
<a href="#">YPTBP00196</a>	UCCOM4 PT ST R AQ 00100	ST OM4 50/125 Pigtail 1m	n/a	n/a	n/a