

1.2. Keystone Jacks



- Cat5e UTP Punch-down Keystone Jack
- Category 5e Compliant
- 3rd Party Approved
- Dual T568A & T568B wiring
- Available in Black & White
- Compatible with UTP cables from 26 AWG to 23 AWG
- RoHS compliant
- 110/LSA IDC Type
- Re-termination: 10 cycles (minimum)

UCCONNECT




Keystone Jack Cat.5e RJ45 UTP 180° Punchdown

Specification

Item	Description
Compatibility	23-26 AWG UTP cables
Dimensions	36.95mm x 24.5mm x 16.94mm

Performance

Item	Description
IDC cap colour code supports both wiring schemes	TIA 568A & 568B
Durability	Modular Jack 800 mating cycles (minimum)
Dielectric withstanding voltage	1000 VDC
Insulation resistance	1000 M / 500 VDC (min)
Contact resistance	20 m (max)
Delay skew	0.2 nsec (max)
Propagation delay	1 nsec (max)
Current rating	1.5 Amps
Input to Output resistance	100 m (max)

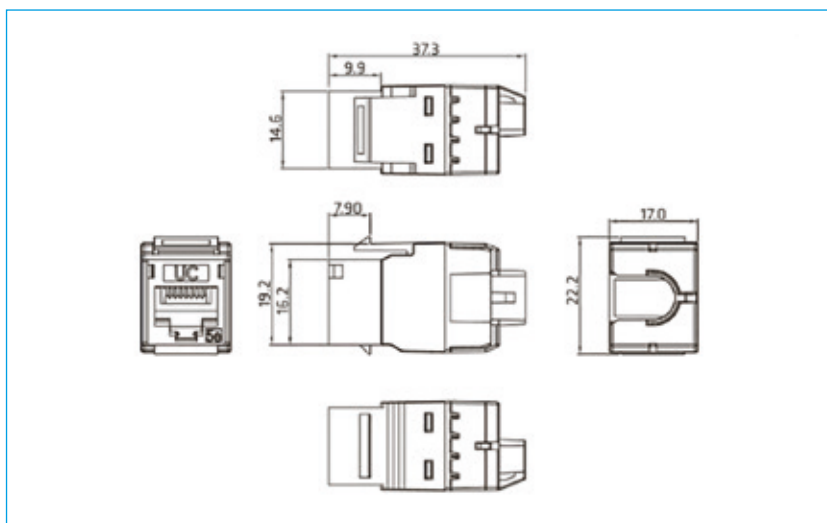

Technical data

Product Code	Product name	Description	Weight	Items per packaging unit
			g	
YMJBP01563	UC C300 MJ TR U WH V1	Keystone Jack Cat.5e RJ45 UTP 180° Punch-down White	9.1	1
YMJBP01564	UC C300 MJ TR U BK V1	Keystone Jack Cat.5e RJ45 UTP 180° Punch-down Black	9.1	1

Related Products

YCJBP01579	UC CACC CJ V1	Punch down Tool for MJTR 8 Series Punch Down Keystones	250	1
YPPBP00344	UC CACC PP U BK 24 1U	19" 1U 24P UTP Keystone Panel Empty 180°	585	1
YPPBP00345	UC CACC PP U BK 48 2U	19" 1U 24P UTP Angle Keystone Panel Empty 180° Foldable patented	585	1
YPPBP00348		19" 2U 48P UTP Patch Panel Empty 180°	720	1