

## 7.4. MPO/MTP Solution

## UC CAOF DB ME BK 12 4U


## 4U 19" Fiber Integrated Technology Distribution Modular Box



- Available in FC, LC, MT-RJ, SC or ST
- Available in OS2, OM1, OM2, OM3 and OM4
- Plug & Play Installation
- Maximum Packing Density
- 100% Tested

## Construction

|                       |   |
|-----------------------|---|
| <b>Dust Cover</b>     | Aluminum, T = 1.5                       |
| <b>Matrix</b>         | Aluminum, T = 1.5                       |
| <b>Adapter Plate</b>  | Without                                 |
| <b>Splice Tray</b>    | Without                                 |
| <b>Panel</b>          | Aluminum                                |
| <b>Plastic Lock</b>   | Latch lock                              |
| <b>Adapter</b>        | MTP (rear side), Duplex LC (front side) |
| <b>Dimension</b>      | H×W×D = 176mm × 482mm × 410mm           |
| <b>Weight</b>         | Appr 5kg (empty panel)                  |
| <b>Surface Finish</b> | Power coating                           |

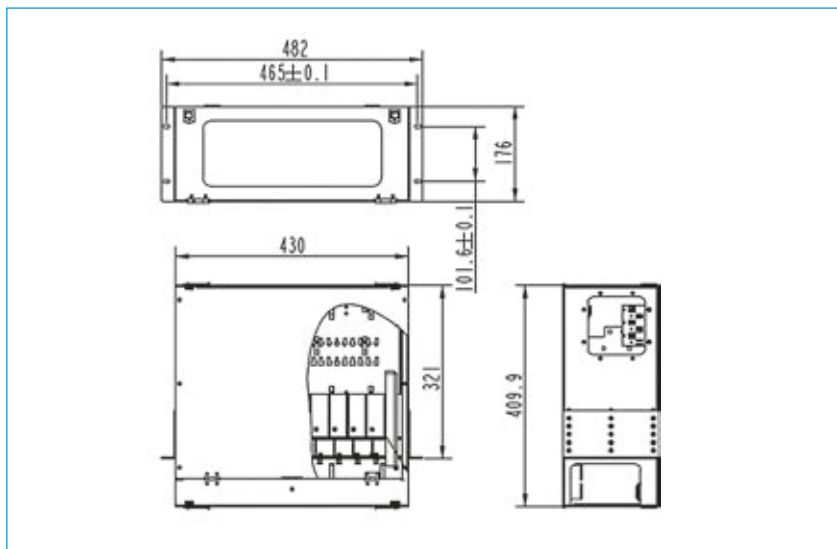

## Technical data

| Item No.          | SAP Description        | Material Description   | Weight | Items per packaging unit |
|-------------------|------------------------|--|--------|--------------------------|
|                   |                        |  | g      |                          |
| <b>YDBBP01453</b> | UC CAOF DB ME BK 12 4U | 4U 19" Fiber Integrated Technology Distribution Modular Box,12 Slot, Empty | 3800   | 1                        |