


KPD-AP-A

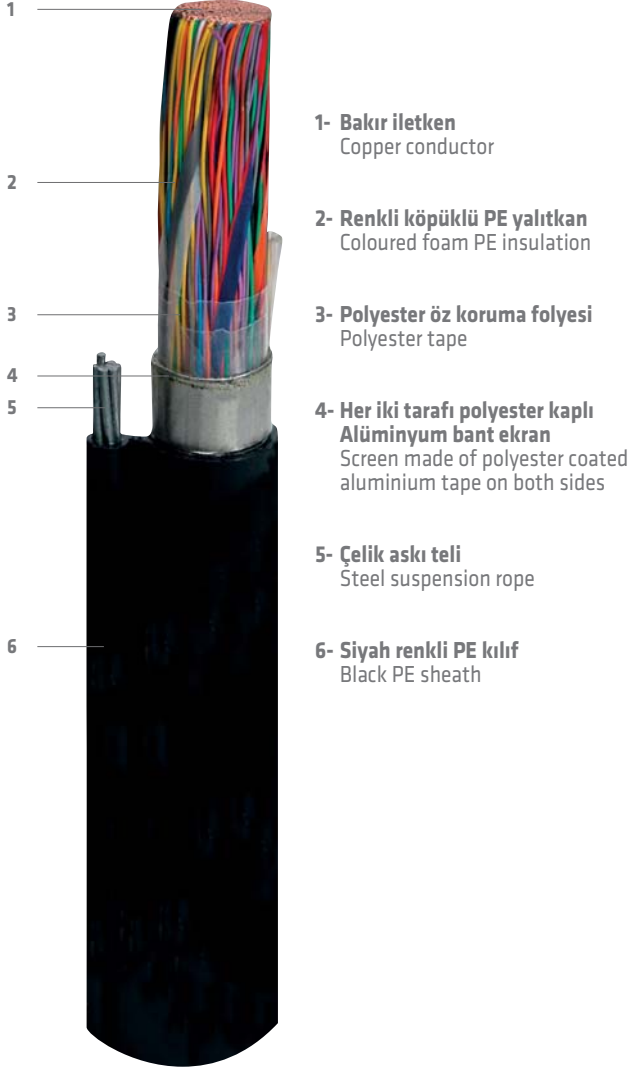

- 1- Bakır iletken
Copper conductor
- 2- Renkli köpüklü PE yalıtkan
Coloured foam PE insulation
- 3- Polyester öz koruma folyesi
Polyester tape
- 4- Her iki tarafı polyester kaplı
Alüminyum bant ekran
Screen made of polyester coated
aluminium tape on both sides
- 5- Çelik askı teli
Steel suspension rope
- 6- Siyah renkli PE kılıf
Black PE sheath

Yapı / Construction

Tavlı elektrolitik bakır iletkenli, 0,4-0,5-0,6 ve 0,9 mm iletken çaplı, köpüklü polietilen yalıtkanlı, kablo özütü dörtlü kablo demetlerinden oluşan, öz üzeri polyester folye sarılı, dolgusuz, alüminyum bant ekranlı, polietilen dış kılıflı, askı halatlı havai hat telefon kablolarıdır.

Annealed electrolytic copper conductor, 0,4-0,5-0,6 and 0,9 mm conductor diameter, foam-skin polyethylene insulated, quads are stranded to form sub-units which are also stranded to make the cable core, wrapped with polyester foil, without filler, aluminum tape screened, with polyethylene outer sheathed, to contains with galvanized steel suspension rope overhead telephone cables.

Teknik Bilgiler / Technical Data

Sabit koşullardaki sıcaklığı : -30 °C, +70 °C
Hareketli koşullardaki sıcaklığı : -5 °C, +50 °C

Temp. for stationary condition : -30 °C, +70 °C
Temp. for moving condition : -5 °C, +50 °C

Kullanıldığı Yerler / Applications

Telefon santrallerinin irtibat ve dağıtım şebekelerinde, abone dağıtım şebekelerinde, ayrıca sinyal ve kumanda devrelerinde kullanılırlar. Beton kanal, PVC veya çimento boru içine çekilebilir veya doğrudan toprağa gömülebilirler.

This cable is used in the connection and distribution networks of the telephone switchboards, subscribers distribution networks and signal and control circuits. They are installed either in trenches, PVC or concrete conduits or buried directly in the soil.



Minimum İşletme
Sıcaklığı
Minimum Operating
Temperature



Maksimum
İşletme Sıcaklığı
Maximum Operating
Temperature



Kurşunsuz
Lead Free



Rijit
Rigid



Bükülme Yarıçapı
Bending Radius
Min 15xD

Kullanıldığı Yerler / Applications



Açıkta
In Free Air



Havai Hat
Aerial

Teknik Özellikler / Technical Features

KPDF-AP-A

Nominal İletken Çapı	Kapasite (En Çok)	20 °C'deki İletken Direnci (En Çok)	20 °C'deki Yalıtım Direnci (En Az)	Test Gerilimi (1dk, Vdc)	Çalışma Gerilimi
Nominal Conductor Diameter	Maximum Capacitance	Maximum Conductor Resistance at 20 °C	Min. Insulation Resistance at 20 °C	Test Voltage (1 min, Vdc)	Operating Voltage
mm	(nF/Km)	Ω/km	M.Ω.km	V	V
	Ort.-Avg	Bir.-Ind.			

0,4	50	56	139,4	>10000	1400	300
0,5	50	56	89,4	>10000	1400	300
0,6	45	51	62,1	>15000	2000	300
0,9	45	51	27,6	>15000	3000	300

Çift Sayısı / İletken Çapı	Kablo Dış Çapı (Yaklaşık)	Net Ağırlık (Yaklaşık)	Dış Kılıf Rengi	Ürün Numarası
Number of Pairs / Conductor Diameter	Overall Diameter of Cable (Apprx.)	Net Weight (Apprx.)	Outer Sheath Colour	Product Number

10x2x0,4 mm	8,41x17,1	133	Siyah - Black	60006464
20x2x0,4 mm	10,48x19,2	172	Siyah - Black	60006475
30x2x0,4 mm	11,74x20,4	206	Siyah - Black	60006482
50x2x0,4 mm	13,76x23,1	292	Siyah - Black	60006487
100x2x0,4 mm	17,52x27,5	469	Siyah - Black	60006468
150x2x0,4 mm	20,61x31,2	649	Siyah - Black	60006472
200x2x0,4 mm	23,27x35,1	867	Siyah - Black	60006479

4x2x0,5 mm	7,29x15,9	115	Siyah - Black	60006486
6x2x0,5 mm	8,17x16,8	129	Siyah - Black	60006491
10x2x0,5 mm	9,3x18,6	172	Siyah - Black	60006465
20x2x0,5 mm	11,36x20,7	225	Siyah - Black	60006476
30x2x0,5 mm	12,8x22,1	272	Siyah - Black	60006483
50x2x0,5 mm	15,11x25,1	389	Siyah - Black	60006488
100x2x0,5 mm	19,61x30,2	642	Siyah - Black	60006469
150x2x0,5 mm	23,12x35	930	Siyah - Black	60006473
200x2x0,5 mm	26,2x40	1.158	Siyah - Black	60006480

10x2x0,6 mm	9,77x19,1	195	Siyah - Black	60006466
20x2x0,6 mm	12,62x22	266	Siyah - Black	60006477
30x2x0,6 mm	14,32x24,3	355	Siyah - Black	60006484
50x2x0,6 mm	17,05x27,7	512	Siyah - Black	60006489
100x2x0,6 mm	23,33x34,2	892	Siyah - Black	60006470
150x2x0,6 mm	26,71x40,5	1.217	Siyah - Black	60006474
200x2x0,6 mm	30,22x45,2	1.600	Siyah - Black	60006481

10x2x0,9 mm	12,68x22	287	Siyah - Black	60006467
20x2x0,9 mm	16,66x26,6	452	Siyah - Black	60006478
30x2x0,9 mm	19,19x29,8	619	Siyah - Black	60006485
50x2x0,9 mm	23,66x35,5	971	Siyah - Black	60006490
100x2x0,9 mm	31,7x46,7	1.744	Siyah - Black	60006471