


Sevk Makaraları Sarma Kapasitesi - Çizelge 1

Capacity of Cable Drums - Table 1

Kablo/ Cable Ø mm	Sevk Makaraları Sarma Kapasitesi - Çizelge 1 / Capacity of Cable Drums - Table 1																	
	SM 4	SM 5	SM 6	SM 7	SM 8	SM 9	SM 10	SM 12	SM 14	SM 16	SM 18	SM 20	SM 22	SM 24	SM 26	SM 28	SM 30	SM 32
	Maksimum kablo uzunlukları (m) / Maximum length of cables (m)																	
6	390	710	1050															
7	280	520	760	1500														
8	215	400	580	1130														
9	170	315	450	900	1225													
10	135	255	370	720	1000	1800												
11	115	210	310	600	820	1500												
12	80	180	260	500	700	1250												
13		150	220	430	590	1050												
14		125	190	370	500	920	1150											
15		110	165	320	440	800	1025											
16		100	145	280	395	710	900	1650										
17			130	250	345	640	800	1500										
18			115	220	310	560	710	1300										
19			100	200	270	500	640	1175										
20				175	250	450	580	1050										
21				165	225	410	530	960	1350									
22				145	200	375	480	870	1250									
23				130	185	340	435	790	1125									
24				125	170	315	405	730	1040	1700								
25				105	155	290	375	680	950	1650								
26					145	265	340	615	870	1520								
27					130	250	320	530	800	1400								
28					120	230	300	520	725	1300								
29					115	215	280	500	700	1225								
30					200	260	460	625	1100									
31					180	240	440	600	1050									
32					170	225	405	570	980	1150								
33					160	215	380	515	925	1075	1125							
34					150	200	360	500	880	1020	1110							
35					140	185	340	470	810	960	1100	1500						
36					130	175	320	450	780	900	1050	1450						
37					120	170	300	425	725	830	990	1420						
38						155	280	400	700	810	925	1350						
39						145	270	385	670	880	1270	1600						
40						135	260	360	640	720	820	1200	1500					
41							250	340	600	700	800	1150	1450					
42							230	320	570	660	750	1100	1370					
43							215	310	550	640	730	1050	1325					
44							205	300	510	610	700	1000	1260					
45							190	280	480	570	660	940	1200					
46								270	470	550	640	900	1130					
47								250	450	535	610	860	1100	1350				
48								240	430	510	580	820	1050	1250				
49								220	410	490	560	790	1000	1220				
50								210	400	470	540	760	970	1170				
51								200	380	450	510	730	930	1125				
52								190	360	430	490	700	900	1075				
53								350	410	470	580	860	1025					
54								400	455	550	650	840	1000	1350				
55								380	440	520	620	800	960	1300				
56								370	425	500	600	780	930	1250				
57								350	410	580	760	900	1200					
58								340	390	560	725	860	1150					
59								330	380	540	700	830	1120					
60								315	360	525	670	800	1075	1200				
61								300	350	500	650	770	1020	1180				
62								290	340	480	625	750	1000	1140				
63								280	325	470	610	720	960	1100				
64								270	315	455	580	700	940	1060				
65								260	305	440	560	680	900	1020				
66								250	290	420	540	660	870	990				
67								240	280	410	520	630	840	960				
68								230	270	400	510	610	800	930				
69								220	260	390	490	580	780	900	1200			
70								210	250	375	475	560	750	880	1180			
71								200	240	360	460	545	730	850	1150			
72								230	350	445	525	705	830	1120				
73								220	340	430	510	680	800	1090				
74								220	330	420	500	670	780	1060				
75								210	320	400	480	640	760	1030				
76								205	310	390	465	625	740	1000				
77								195	300	370	450	600	720	970				
78								190	290	360	440	585	700	950				
79								185	270	350	420	560	680	920				
80								175	270	340	410	550	660	900				
81								240	300	370	520	650	880					
82								230	290	360	500	630	860					
83								220	280	350	500	620	840					
84								210	280	340	480	600	810					
85								210	270	330	470	590	780					
86								200	260	330	460	570	780					
87								200	260	320	450	560	760					
88								250	310	440	540	670	900					
89								240	300	430	530	660	890					
90								240	300	420	520	650	880					
91								230	290	410	510	640	870					
92								230	280	400	500	630	860					
93								220	280	390	490	620	850					
94								270	380	470	570	690	930					
95								260	370	460	560	680	920					
96								260	370	450	560	680	920					
97								250	360	440	550	670	910					
98								250	350	430	540	660	900					
99								240	340	420	530	650	890					
100								240	340	420	530	650	890					
101								330	410	550								
102								320	400	540								
103								320	390	530								
104								310	380	520								
105								300	380	510								
106								300	370	500								
107								290	360	490								
108								290	350	480								
109								280	350	470								
110								270	340	460								

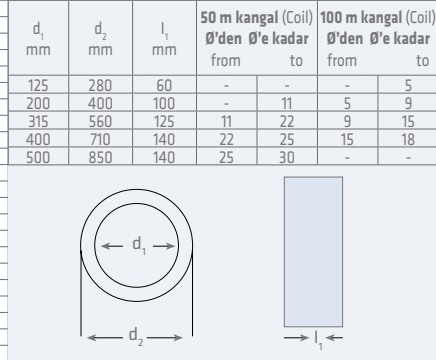

Sevk Makaraları Çizelge 2 / Sevk Makaraları Çizelge 2a

Cable Drums Table 2 / Cable Drums Table 2a

